

A/D accuracy 10bit

R8C/26-27 Group

Topr = -40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz φAD=10MHz sample and hold=on Repeat mode

Absolute accuracy
-1.97LSB

Prepared on Sep. 07, 2007

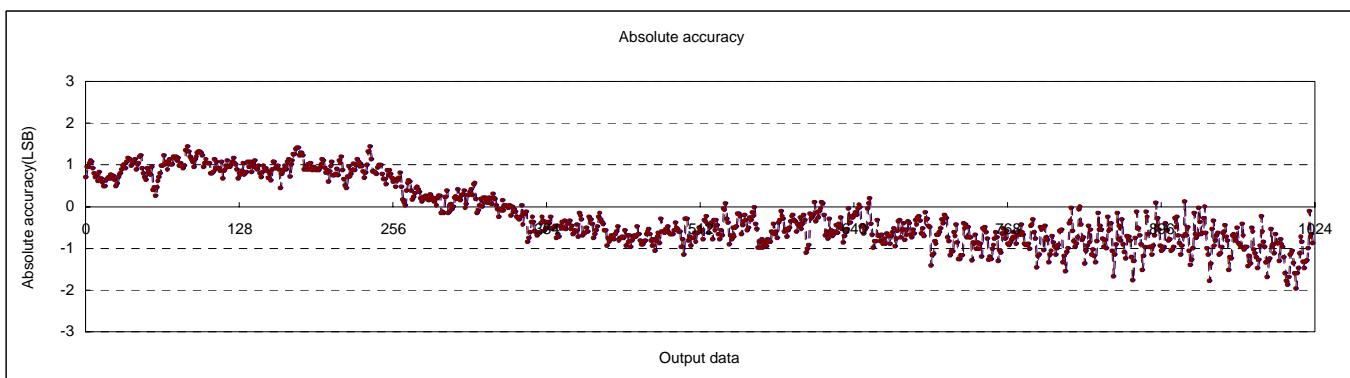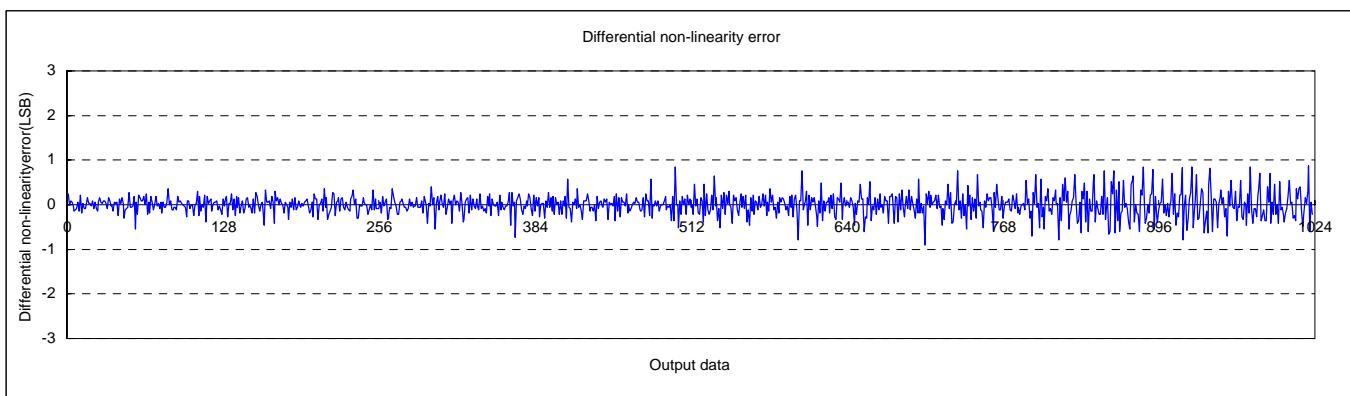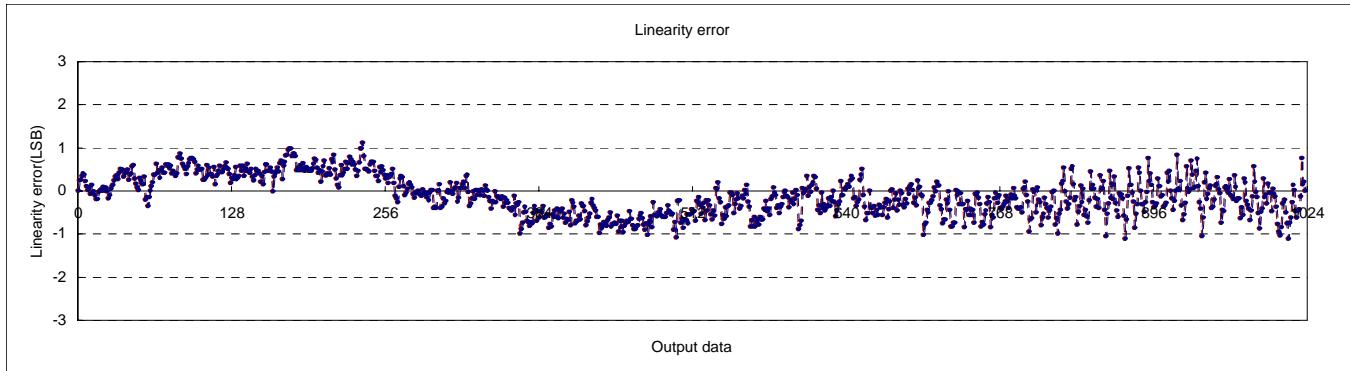

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.